

追加規格 以紅字表示

六角支柱 附嵌入部


— 嵌入部固定 / 嵌入部指定 —

大訂單
對應
BIG ORDER

◆ 非型錄規格商品請參照 P.131
◆ CAD資料夾名稱 : 31_Posts

與LKC併用後L尺寸可以0.1mm為單位指定長度。

六角支柱附嵌入部

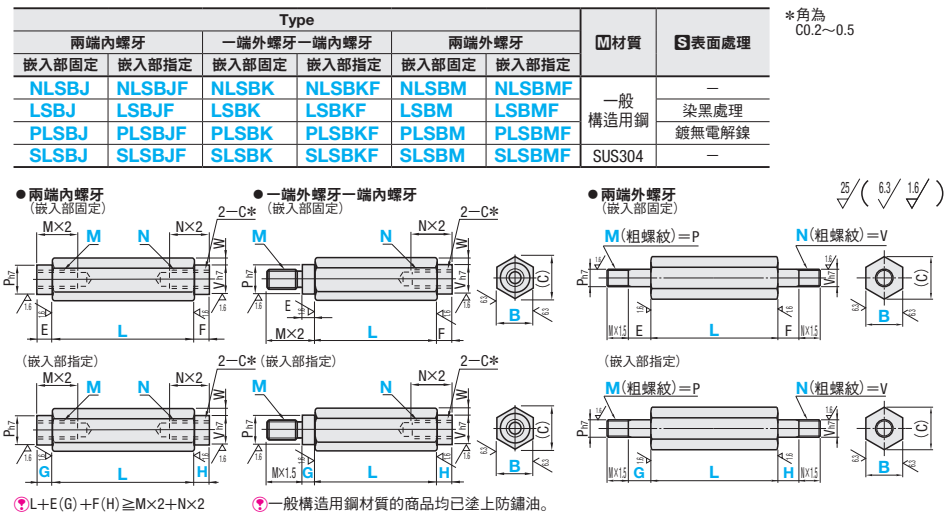

*角為
C0.2~0.5

兩端內螺牙

型式 Type	B	L 指定單位0.5mm	M (粗螺紋) · N (粗螺紋) 選擇		G 指定單位1mm ▼僅嵌入部指定	H 指定單位1mm ▼僅嵌入部指定	E	F	P	V	W	(C)
			M	N								
嵌入部固定 一般構造用鋼 NLSBJ LSBJ PLSBJ SUS304 SLSBJ	8	15~250	3 4	4 5	2~4	2~4	4	4	6	6	1	9.2
	10	15~350	3 4 5	4 5	2~5	2~5	5	5	8	8	1	11.5
	12	20~500	4 5 6	4 5 6	2~6	2~6	6	6	10	10	1	13.9
	13	25~500	4 5 6	4 5 6	2~6	2~6	6	6	10	10	1.5	15
	14	25~600	5 6 8	5 6 8	2~8	2~8	8	8	12	12	1	16.2
	17	25~600	5 6 8	5 6 8	2~8	2~8	8	8	12	12	2.5	19.6
	19	40~600	5 6 8 10 12	5 6 8 10 12	2~10	2~10	10	10	16	16	1.5	21.9
	24	50~700	5 6 8 10 12 16	5 6 8 10 12 16	2~12	2~12	12	12	20	20	2	27.7
嵌入部指定 一般構造用鋼 NLSBJ LSBJ PLSBJ SUS304 SLSBJ	27	50~800	5 6 8 10 12 16	5 6 8 10 12 16	2~16	2~16	16	16	24	24	1.5	31.2
	27W	50~800	5 6 8 10 12 16	5 6 8 10 12 16	2~16	2~16	16	16	24	24	3.5	31.2
	30	60~1000	5 6 8 10 12 16 20	5 6 8 10 12 16 20	2~16	2~16	16	16	28	28	1	34.6
	30W	60~1000	5 6 8 10 12 16 20	5 6 8 10 12 16 20	2~16	2~16	16	16	24	24	3	34.6
	32	60~1000	5 6 8 10 12 16 20	5 6 8 10 12 16 20	2~20	2~20	20	20	30	30	1	36.9
	32W	60~1000	5 6 8 10 12 16 20	5 6 8 10 12 16 20	2~20	2~20	20	20	24	24	4	36.9
	32W	60~1000	5 6 8 10 12 16 20	5 6 8 10 12 16 20	2~20	2~20	20	20	24	24	4	36.9
	32W	60~1000	5 6 8 10 12 16 20	5 6 8 10 12 16 20	2~20	2~20	20	20	24	24	4	36.9

一端外螺牙一端內螺牙


型式 Type	B	L 指定單位0.5mm	M (粗螺紋) · N (粗螺紋) 選擇		G 指定單位1mm ▼僅嵌入部指定	H 指定單位1mm ▼僅嵌入部指定	E	F	P	V	W	(C)
			M	N								
嵌入部固定 一般構造用鋼 NLSBK LSBK PLSBK SUS304 SLSBK	8	20~250	3 4 5	4 5	2~4	2~4	4	4	6	6	1	9.2
	10	20~350	3 4 5 6	4 5	2~5	2~5	5	5	8	8	1	11.5
	12	25~500	4 5 6 8	4 5 6	2~6	2~6	6	6	10	10	1	13.9
	13	25~500	4 5 6 8	4 5 6	2~6	2~6	6	6	10	10	1.5	15
	14	30~600	5 6 8 10	5 6 8	2~8	2~8	8	8	12	12	1	16.2
	17	30~600	5 6 8 10	5 6 8	2~8	2~8	8	8	12	12	2.5	19.6
	19	45~600	5 6 8 10 12 16	5 6 8 10 12	2~10	2~10	10	10	16	16	1.5	21.9
	24	55~700	5 6 8 10 12 16 20	5 6 8 10 12 16	2~12	2~12	12	12	20	20	2	27.7
嵌入部指定 一般構造用鋼 NLSBK LSBK PLSBK SUS304 SLSBK	27	55~800	5 6 8 10 12 16 20 24	5 6 8 10 12 16	2~16	2~16	16	16	24	24	1.5	31.2
	27W	55~800	5 6 8 10 12 16 20 24	5 6 8 10 12 16	2~16	2~16	16	16	20	20	3.5	31.2
	30	65~1000	5 6 8 10 12 16 20 24	5 6 8 10 12 16 20	2~16	2~16	16	16	28	28	1	34.6
	30W	65~1000	5 6 8 10 12 16 20 24	5 6 8 10 12 16 20	2~16	2~16	16	16	24	24	3	34.6
	32	65~1000	5 6 8 10 12 16 20 24	5 6 8 10 12 16 20	2~20	2~20	20	20	30	30	1	36.9
	32W	65~1000	5 6 8 10 12 16 20 24	5 6 8 10 12 16 20	2~20	2~20	20	20	24	24	4	36.9
	32W	65~1000	5 6 8 10 12 16 20 24	5 6 8 10 12 16 20	2~20	2~20	20	20	24	24	4	36.9
	32W	65~1000	5 6 8 10 12 16 20 24	5 6 8 10 12 16 20	2~20	2~20	20	20	24	24	4	36.9

兩端外螺牙

型式 Type	B	L 指定單位0.5mm	M (粗螺紋) · N (粗螺紋) 選擇		G 指定單位1mm ▼僅嵌入部指定	H 指定單位1mm ▼僅嵌入部指定	E	F	P	V	W	(C)
			M	N								
嵌入部固定 一般構造用鋼 NLSBM LSBM PLSBM SUS304 SLSBM	8	20~250	3 4 5 6	4 5	2~4	2~4	4	4	6	6	1	9.2
	10	20~350	3 4 5 6 8	4 5	2~5	2~5	5	5	8	8	1	11.5
	12	25~500	4 5 6 8 10	4 5 6	2~6	2~6	6	6	10	10	1	13.9
	13	25~500	4 5 6 8 10	4 5 6	2~6	2~6	6	6	10	10	1.5	15
	14	30~600	5 6 8 10 12	5 6 8	2~8	2~8	8	8	12	12	1	16.2
	17	30~600	5 6 8 10 12	5 6 8	2~8	2~8	8	8	12	12	2.5	19.6
	19	45~600	5 6 8 10 12 16	5 6 8 10 12	2~10	2~10	10	10	16	16	1.5	21.9
	24	55~700	5 6 8 10 12 16 20	5 6 8 10 12 16	2~12	2~12	12	12	20	20	2	27.7
嵌入部指定 一般構造用鋼 NLSBM LSBM PLSBM SUS304 SLSBM	27	55~800	5 6 8 10 12 16 20 24	5 6 8 10 12 16	2~16	2~16	16	16	24	24	1.5	31.2
	27W	55~800	5 6 8 10 12 16 20 24	5 6 8 10 12 16	2~16	2~16	16	16	20	20	3.5	31.2
	30	65~1000	5 6 8 10 12 16 20 24	5 6 8 10 12 16 20	2~16	2~16	16	16	28	28	1	34.6
	30W	65~1000	5 6 8 10 12 16 20 24	5 6 8 10 12 16 20	2~16	2~16	16	16	24	24	3	34.6
	32	65~1000	5 6 8 10 12 16 20 24	5 6 8 10 12 16 20	2~20	2~20	20	20	30	30	1	36.9
	32W	65~1000	5 6 8 10 12 16 20 24	5 6 8 10 12 16 20	2~20	2~20	20	20	24	24	4	36.9
	32W	65~1000	5 6 8 10 12 16 20 24	5 6 8 10 12 16 20	2~20	2~20	20	20	24	24	4	36.9
	32W	65~1000	5 6 8 10 12 16 20 24	5 6 8 10 12 16 20	2~20	2~20	20	20	24	24	4	36.9

Order 訂購格式	型式	L	M	N	G	H
	NLSBJ10	350	M5	N4		
	LSBJ27W	600	M8	N8		
	NLSBMF10	300	M5	N5	G3	H2

L尺寸公差	公差
L 15~300	±0.1
L 300.5~600	±0.3
L 600.5~800	±0.4

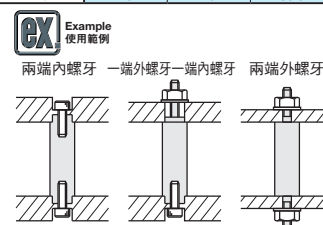

NTS Price 價格 WEB WOS

兩端內螺牙

型式 Type	B	NTS標準單價			
		最短L~200	L200.5~400	L400.5~600	L600.5~800
一般構造用鋼 NLSBJ NLSBJF	8	-	-	-	-
	10	-	-	-	-
	12	-	-	-	-
	13	-	-	-	-
	14	-	-	-	-
	17	-	-	-	-
	19	-	-	-	-
	24	-	-	-	-
	27	-	-	-	-
	27W	-	-	-	-
	30	-	-	-	-
一般構造用鋼 染黑處理 LSBJ LSBJF	30W	-	-	-	-
	32	-	-	-	-
	32W	-	-	-	-
	8	-	-	-	-
	10	-	-	-	-
	12	-	-	-	-
	13	-	-	-	-
	14	-	-	-	-
	17	-	-	-	-
	19	-	-	-	-
	一般構造用鋼 鍍無電解鍍 PLSBJ PLSBJF	24	-	-	-
27		-	-	-	-
27W		-	-	-	-
30		-	-	-	-
30W		-	-	-	-
32		-	-	-	-
32W		-	-	-	-
8		-	-	-	-
10		-	-	-	-
12		-	-	-	-
13		-	-	-	-
一般構造用鋼 鍍無電解鍍 PLSBK PLSBKF	14	-	-	-	-
	17	-	-	-	-
	19	-	-	-	-
	24	-	-	-	-
	27	-	-	-	-
	27W	-	-	-	-
	30	-	-	-	-
	30W	-	-	-	-
	32	-	-	-	-
	32W	-	-	-	-

一端外螺牙一端內螺牙

型式 Type	B	NTS標準單價			
		最短L~200	L200.5~400	L400.5~600	L600.5~800
一般構造用鋼 NLSBK NLSBKF	8	-	-	-	-
	10	-	-	-	-
	12	-	-	-	-
	13	-	-	-	-
	14	-	-	-	-
	17	-	-	-	-
	19	-	-	-	-
	24	-	-	-	-
	27	-	-	-	-
	27W	-	-	-	-
	30	-	-	-	-
一般構造用鋼 染黑處理 LSBK LSBKF	30W	-	-	-	-
	32	-	-	-	-
	32W	-	-	-	-
	8	-	-	-	-
	10	-	-	-	-
	12	-	-	-	-
	13	-	-	-	-
	14	-	-	-	-
	17	-	-	-	-
	19	-	-	-	-
	一般構造用鋼 鍍無電解鍍 PLSBK PLSBKF	24	-	-	-
27		-	-	-	-
27W		-	-	-	-
30		-	-	-	-
30W		-	-	-	-
32		-	-	-	-
32W		-	-	-	-
8		-	-	-	-
10		-	-	-	-
12		-	-	-	-
13		-	-	-	-
一般構造用鋼 鍍無電解鍍 SUS304 SLSBK SLSBKF	14	-	-	-	-
	17	-	-	-	-
	19	-	-	-	-
	24	-	-	-	-
	27	-	-	-	-
	27W	-	-</		