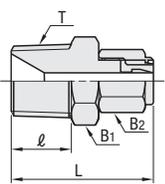


■直柱型

MCPTK

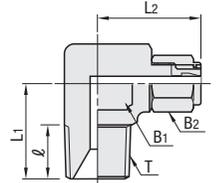
RoHS

材質 SUS316

型式 Type	適用軟管 外徑 (mm)	T R (PT) 連接	T R (PT)	通用軟管 內徑 (mm)	L	ℓ	B ₁ (二面寬度)	B ₂ (二面寬度)	NTS標準單價 1~4 pcs	NTS折扣單價 5~20
MCPTK	3.2	1	1/8	1.6	24	9	10	10		
		2	1/8	2	24	9	10	10		
	4	1	1/8	2	26	11	14			
		2	1/8	2	26	11	14			
	6	1	1/8	4	28.5	11	14	12		
		2	1/8	4	30	12	17			
	8	1	1/8	6	28	9	14	14		
		2	1/4	6	30	11	14			
	10	3	3/8	8	31	12	17			
		2	1/4	8	32	11	17			
	12	3	3/8	10	33	12	17	19		
		4	1/2	10	36	15	22			

■L型

MCLPTK

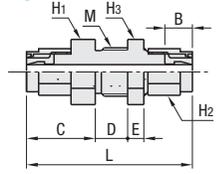
RoHS

材質 SUS316

型式 Type	適用軟管 外徑 (mm)	T R (PT) 連接	T R (PT)	通用軟管 內徑 (mm)	L ₁	L ₂	ℓ	B ₁ (二面寬度)	B ₂ (二面寬度)	NTS標準單價 1~4 pcs	NTS折扣單價 5~20
MCLPTK	3.2	1	1/8	1.6	18	20	9	12	10		
		2	1/8	2	18	20	9	12	10		
	4	1	1/8	4	21	21	11	14			
		2	1/8	4	21	21	11	14			
	6	1	1/8	6	18	21.5	9	12	12		
		2	1/4	6	21	22.5	11	14			
	8	1	1/8	8	19	24	9	14	14		
		2	1/4	8	21	24	11	14			
	10	3	3/8	10	23	25	12	17			
		2	1/4	10	22	26.5	11	17			
	12	3	3/8	12	23	26.5	12	17	19		
		4	1/2	12	29	28.5	15	22			

■板安裝型

MCBU

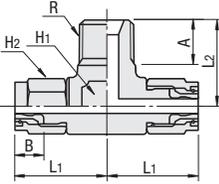
RoHS

材質 SUS316

型式 Type	No.	通用軟管 外徑 (mm)	通用軟管 內徑 (mm)	L	B	二面寬度 H ₁ H ₂ H ₃	C	D	E	M	NTS標準單價 1~4 pcs	NTS折扣單價 5~20
MCBU	4	4	2.5	41	6	14 10 14	17	8	4	M12x1.0		
	6	6	4	44	7	17 12 17	18.5	8	4	M14x1.0		
	8	8	6	47	7.5	19 14 19	20	8	4	M16x1.0		
	10	10	8	50	8	22 17 22	21.5	8	4	M18x1.0		
12	12	10	54	9.5	24 19 24	23	8	5	M20x1.0			

■T型

MCTPT

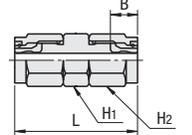
RoHS

材質 SUS316

型式 Type	No.	螺牙尺寸 R (PT)	通用軟管 外徑 (mm)	通用軟管 內徑 (mm)	L ₁	L ₂	A	B	二面寬度 H ₁ H ₂	NTS標準單價 1~9 pcs	NTS折扣單價 10~20
MCTPT	4-1	1/8	4	2.5	20	18	9	6	12 10		
	4-2	1/4	4	2.5	21	21	11	6	14 10		
	6-1	1/8	6	4	21.5	18	9	7	12 12		
	6-2	1/4	6	4	22.5	21	11	7	14 12		
	8-15	1/8	8	6	23.5	19	9	7.5	14 14		
	8-1	1/8	8	6	23.5	19	9	7.5	14 14		
	8-2	1/4	8	6	23.5	21	11	7.5	14 14		
	8-3	3/8	8	6	25	23	12	7.5	17 14		
	8-36	3/8	8	6	25	23	12	7.5	17 14		
	10-2	1/4	10	8	28.5	25	11	8	22 17		
	10-36	3/8	10	8	28.5	26	12	8	22 17		
	10-3	3/8	10	8	28.5	26	12	8	22 17		

■套接型

MCUN

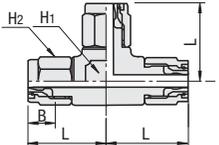
RoHS

材質 SUS316

型式 Type	No.	通用軟管 外徑 (mm)	通用軟管 內徑 (mm)	L	B	二面寬度 H ₁ H ₂	NTS標準單價 1~9 pcs	NTS折扣單價 10~20
MCUN	4	4	2.5	28	6	10 10		
	6	6	4	32	7	12 12		
	8	8	6	36	7.5	14 14		
	10-6	10	6.5	40	8	17 17		
	10	10	8	40	8	17 17		
	12-8	12	8	44	9.5	17 19		
	12-9	12	9	44	9.5	17 19		
	12	12	10	44	9.5	17 19		

■套接T型

MCUT

RoHS

材質 SUS316

型式 Type	No.	通用軟管 外徑 (mm)	通用軟管 內徑 (mm)	L	B	二面寬度 H ₁ H ₂	NTS標準單價 1~9 pcs	NTS折扣單價 10~20
MCUT	4	4	2.5	20	6	12 10		
	6	6	4	21.5	7	12 12		
	8-5	8	5	23.5	7.5	14 14		
	8	8	6	23.5	7.5	14 14		
	10	10	8	28.5	8	22 17		
	12-8	12	8	30	9.5	22 19		

Order 訂購範例

型式 T

MCPTK4 - 1

Delivery 出貨日

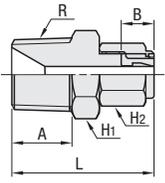
WEB WOS

NTS Price 價格

WEB WOS

■半套接型

MCTPTY

RoHS

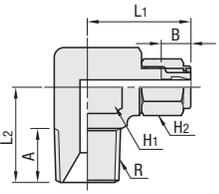
材質 SUS316

型式 Type	No.	螺牙尺寸 R (PT)	通用軟管 外徑 (mm)	通用軟管 內徑 (mm)	L	A	B	二面寬度 H ₁ H ₂	NTS標準單價 1~9 pcs	NTS折扣單價 10~30
MCTPTY	4-1	1/8	4	2.5	24	9	6	10 10		
	4-2	1/4	4	2.5	26	11	6	14 10		
	8-1	1/8	8	6	28	9	7.5	14 14		
	8-2	1/4	8	6	30	11	7.5	14 14		
	8-3	3/8	8	6	31	12	7.5	17 14		
	10-2	1/4	10	8	32	11	8	17 17		
	10-3	3/8	10	8	33	12	8	17 17		
	10-4	1/2	10	8	36	15	8	22 17		
	12-2	1/4	12	10	34	11	9.5	17 19		
	12-3	3/8	12	10	35	12	9.5	17 19		
	12-4	1/2	12	10	38	15	9.5	22 19		

MCPTK與MCTPTY的差異在於通用軟管的內徑不同。
請配合欲使用之軟管來選定。

■半L型

MCUNE

RoHS

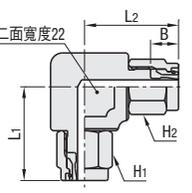
材質 SUS316

型式 Type	No.	螺牙尺寸 R (PT)	通用軟管 外徑 (mm)	通用軟管 內徑 (mm)	L ₁	L ₂	A	B	二面寬度 H ₁ H ₂	NTS標準單價 1~9 pcs	NTS折扣單價 10~30
MCUNE	4-1	1/8	4	2.5	20	18	9	6	12 10		
	4-2	1/4	4	2.5	21	21	11	6	14 10		
	8-1	1/8	8	6	24	19	9	7.5	14 14		
	8-2	1/4	8	6	24	21	11	7.5	14 14		
	8-3	3/8	8	6	25	23	12	7.5	17 14		
	10-2	1/4	10	8	26.5	22	11	8	17 17		
	10-3	3/8	10	8	26.5	23	12	8	17 17		
	10-4	1/2	10	8	28.5	29	15	8	22 17		
	12-2	1/4	12	10	27.5	23	11	9.5	17 19		
	12-3	3/8	12	10	30	27	12	9.5	22 19		
	12-4	1/2	12	10	30	30	15	9.5	22 19		

MCPLTK與MCUNE的差異在於通用軟管的內徑不同。
請配合欲使用之軟管來選定。

■套接L型

MCUE

RoHS

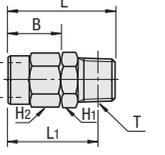
材質 SUS316

*No.6的二面寬度為17。

型式 Type	No.	通用軟管 外徑 (mm)	通用軟管 內徑 (mm)	L ₁	L ₂	B	二面寬度 H ₁ H ₂	NTS標準單價 1~4 pcs	NTS折扣單價 5~10
MCUE	6	6	4	23.5	23.5	7	12 12		
	8	8	6	27	27	7.5	14 14		
	10	10	8	28.5	28.5	8	17 17		
	12	12	10	30	30	9.5	19 19		

■接頭型

TJBNC

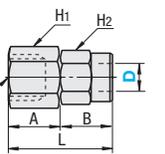
RoHS

材質 黃銅

型式 Type	No.	軟管內徑 (mm)	L	L ₁	B	H ₁	H ₂	T R (PT)	質量 (g)	NTS標準單價 1~9 pcs	NTS折扣單價 10~20
TJBNC	6	1	4	26	22	12	12	R1/8	18		
		2	4	28.5	22.5	14	12	R1/4	26		
	8	1	6	28	24	14	14	R1/8	25		
		2	6	30	24	14	14	R1/4	30		
	10	3	8	31	24.6	17	14	R3/8	41		
		2	8	32	26	17	17	R1/4	43		
	12	3	10	33	26.6	17	17	R3/8	50		
		2	10	34	28	17	19	R1/4	49		
	12	3	12	35	28.6	17	19	R3/8	57		

■管接頭型

TJBSC

RoHS

材質 黃銅

型式 Type	No.	軟管內徑 (mm)	L	A	B	H ₁	H ₂	T Rc (PT) · G (PF)	質量 (g)	NTS標準單價 1~9 pcs	NTS折扣單價 10~20
TJBSC	6	1	4	23.5	11	12.5	14	12	Rc1/8	20	
		2	4	26.5	14	17	14	12	Rc1/4	31	
	8	2F	6	28	14	17	14	17	Rc1/4	33	
		3	6	28	14	17	14	17	G1/4	33	
	10	2F	8	30	16	22	14	17	Rc3/8	51	
		3	8	29.5	14	17	17	17	G1/4	42	
	12	2F	10	31.5	16	22	17	17	Rc3/8	59	
		3	10	31	14	19	19	19	Rc1/4	55	
	12	2F	12	31	14	17	19	19	G1/4	55	
		3	12	33	16	22	19	19	Rc3/8	66	

規格

材質	SUS316	黃銅
使用流體	空氣·水	
使用溫度範圍	-65~260°C (空氣) 0~100°C (水)	-40~80°C
最高使用壓力	以軟管最高使用壓力為準	
使用真空壓力	-100kPa	

構造圖



■特長

螺帽與套筒成一體,配管時軟管不會扭曲。

套筒 止動環 螺帽 本體

Order 訂購範例

型式 MCUE6

Delivery 出貨日

WEB WOS

NTS Price 價格

WEB WOS