 




4面銑面(壓延)



4面銑面精密壓延

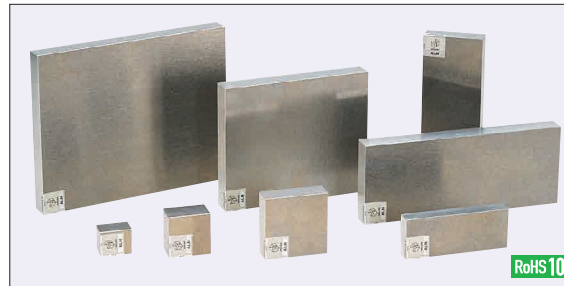

ALNH

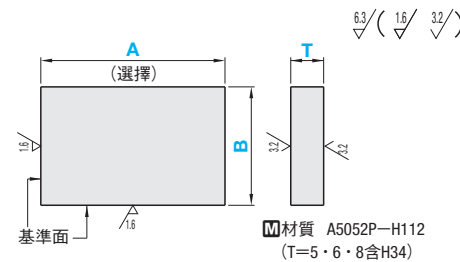

RoHS 10

Order 訂購範例: 型式 ALNH - A - B - T = 350 - 200 - 10


Delivery 出貨日: WEB WOS

Price 價格: NTS WEB WOS


■精密度基準

- 平面度 每1000mm為1.5以下
- T的尺寸公差: 5 6 8 10 12·15 20 25 30  
±0.35 ±0.45 ±0.5 ±0.6 ±0.7 ±0.8 ±0.9 ±1.0
- A·B的尺寸公差: 25~100 101~250 251~500  
±0.2 ±0.25 ±0.4
- 基準面直角度 每100mm為0.015以下
- 外圍倒角 C0.3以下

型式	A	B	T	5	6	8	10	12	15	20	25	30				
ALNH (標準尺寸)	100	100	100													
	125															
	150															
	160															
	200															
	250															
	300															
	350															
	400															
	450															
	500															
	125	125	100													
	150															
	160															
	200															
	250															
	300															
	350															
	400															
	450															
	500															
	150	150	100													
	160															
	200															
	250															
	300															
	350															
	400															
	450															
	500															
160	160			100												
200																
250																
300																
350																
400																
450																
500																
200		200	100													
250																
300																
350																
400																
450																
500																
250	250			100												
300																
350																
400																
450																
500																
300		300	100													
350																
400																
450																
500																

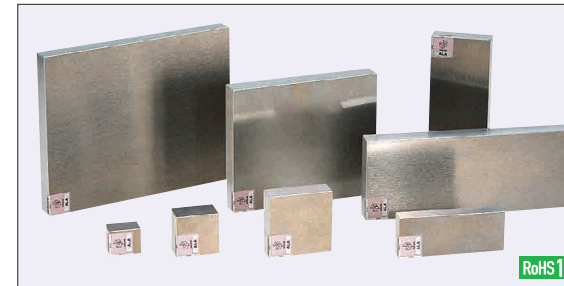

ALAH

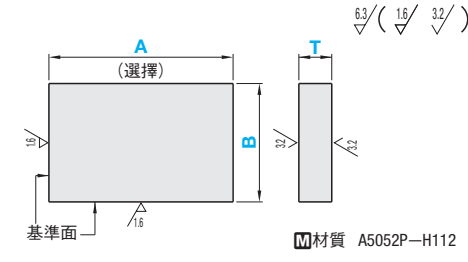

RoHS 10

Order 訂購範例: 型式 ALAH - A - B - T = 300 - 100 - 12

Delivery 出貨日: WEB WOS

Price 價格: NTS WEB WOS

■精密度基準

- 平面度 每1000mm為0.4以下
- T的尺寸公差: 5·6 8·10·12 15 20 25 30  
±0.04 ±0.05 ±0.08 ±0.10 ±0.12 ±0.15
- A·B的尺寸公差: 100~250 251~500  
±0.25 ±0.4
- 基準面直角度 每100mm為0.015以下
- 外圍倒角 C0.3以下

型式	A	B	T	5	6	8	10	12	15	20	25	30				
ALAH (標準尺寸)	100	100	100													
	125															
	150															
	160															
	200															
	250															
	300															
	350															
	400															
	450															
	500															
	125	125	100													
	150															
	160															
	200															
	250															
	300															
	350															
	400															
	450															
	500															
	150	150	100													
	160															
	200															
	250															
	300															
	350															
	400															
	450															
	500															
160	160			100												
200																
250																
300																
350																
400																
450																
500																
200		200	100													
250																
300																
350																
400																
450																
500																
250	250			100												
300																
350																
400																
450																
500																
300		300	100													
350																
400																
450																
500																