

WASHER ASSEMBLED CROSS RECESSED SCREWS


附墊圈十字孔盆頭小螺絲

— 單品販售 —

CAD資料夾名稱: 34_Screws



RoHS

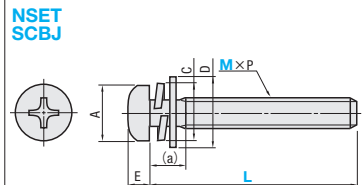

NSET	
螺柱	M 材質: 相當於SWCH
墊圈	彈簧墊圈 JIS B 1251 平墊圈 JIS B 1256
S表面處理	三價鉻酸鹽


SCBJ	
螺柱	M 材質: 相當於SUS304
墊圈	彈簧墊圈 JIS B 1251 平墊圈 JIS B 1256

MxP	A	E	C (最大)	D	(a)	十字孔 No.
2 × 0.4	3.5	1.3	4.0	6.0	2.1	1
2.5 × 0.45	4.5	1.7	4.8	6.5	2.7	1
2.6 × 0.45	4.5	1.7	4.8	7.5	2.7	1
3 × 0.5	5.5	2.0	5.5	8.0	3.0	2
4 × 0.7	7.0	2.6	7.0	10.0	4.4	2
5 × 0.8	9.0	3.3	8.5	12.0	5.4	2
6 × 1.0	10.5	3.9	11.5	13.0	6.9	3

型式	Type	M-L	NSET		SCBJ		
			NTS標準單價	NTS折扣單價	NTS標準單價	NTS折扣單價	
NSET SCBJ	2	4					
		5					
		6					
	2.5	4					
		5					
		6					
		8					
		10					
	2.6	4					
		5					
		6					
		8					
		10					
	3	5					
		6					
8							
10							
12							
14							
16							
20							
25							
30							
35							
40							
45							
50							
4		5					
	6						
	8						
	10						
	12						
	14						
	16						
	20						
	25						
	30						
	35						
	40						
	45						
	50						
	5	8					
10							
12							
14							
16							
20							
25							
30							
35							
40							
45							
50							
6		10					
		12					
		14					
	16						
	20						
	25						
	30						
	35						
	40						
	45						
	50						



PSET PSETS

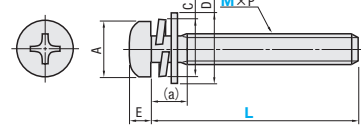


PSET	
螺柱	M 材質: 相當於SWCH
墊圈	彈簧墊圈 JIS B 1251 平墊圈 JIS B 1256
S表面處理	三價鉻酸鹽


PSETS	
螺柱	M 材質: 相當於SUS304
墊圈	彈簧墊圈 JIS B 1251 平墊圈 JIS B 1256

MxP	A	E	C (最大)	D	(a)	十字孔 No.
3 × 0.5	5.5	2.0	5.5	6.0	3.0	2
4 × 0.7	7.0	2.6	7.0	8.0	4.4	2
5 × 0.8	9.0	3.3	8.5	10.0	5.4	2
6 × 1.0	10.5	3.9	11.5	11.5	6.9	3

型式	Type	M-L	PSET		PSETS	
			NTS標準單價	NTS折扣單價	NTS標準單價	NTS折扣單價
PSET PSETS	3	6				
		8				
		10				
	4	6				
		8				
		10				
		12				
		15				
	5	8				
		10				
		12				
		15				
		20				
	6	10				
		12				
15						
20						

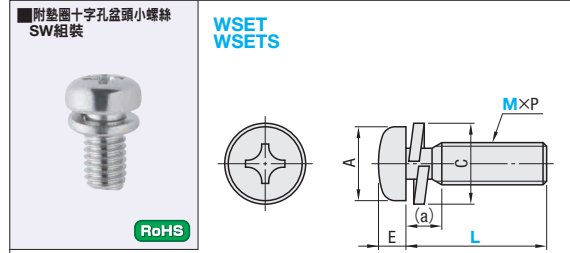


WSET WSETS

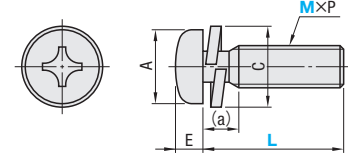


RoHS

WSET		WSETS	
螺柱	M 材質: 相當於SWCH	螺柱	M 材質: 相當於SUS304
墊圈	彈簧墊圈 JIS B 1251 平墊圈 JIS B 1256	墊圈	彈簧墊圈 JIS B 1251 平墊圈 JIS B 1256
S表面處理	三價鉻酸鹽	S表面處理	三價鉻酸鹽

MxP	A	E	C (最大)	(a)	十字孔 No.
3 × 0.5	5.5	2.0	5.5	2.4	2
4 × 0.7	7.0	2.6	7.0	3.5	2
5 × 0.8	9.0	3.3	8.5	4.3	2
6 × 1.0	10.5	3.9	11.5	5.1	3

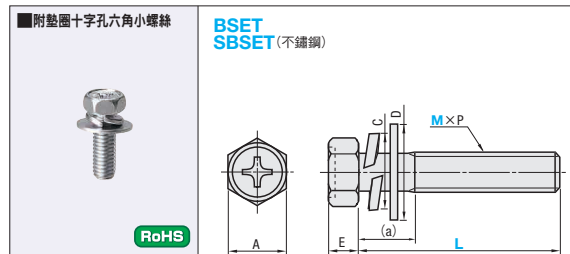

BSET SBSET (不鏽鋼)

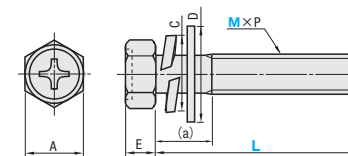

RoHS

BSET		SBSET	
螺柱	M 材質: 構造用合金鋼 螺牙 JIS 0209 (6g)	螺柱	M 材質: 相當於SUS304 ※強度區分 相當於A2-50 螺牙 JIS 0209 (6g)
墊圈	彈簧墊圈 JIS B1251 平墊圈 JIS B1256	墊圈	彈簧墊圈 JIS B1251 平墊圈 JIS B1256
S表面處理	三價鉻酸鹽	S表面處理	滾筒研磨・鈍化處理

MxP	A	E	C	D	(a)
4 × 0.7	7	2.8	7.0	10	4.4
5 × 0.8	8	3.5	8.5	12	5.2
6 × 1.0	10	4.0	11.5	13	6.3
8 × 1.25	13	5.5	14.5	18	8.4

(a) 為螺柱的座面起到完全螺牙部的參考尺寸(最大值)。

型式	Type	M-L	WSET				WSETS					
			NTS標準單價	NTS折扣單價	NTS標準單價	NTS折扣單價	NTS標準單價	NTS折扣單價	NTS標準單價	NTS折扣單價		
WSET WSETS	3	6										
		8										
		10										
	4	8										
		10										
		12										
		15										
		20										
	5	8										
		10										
		12										
		15										
		20										
	6	10										
		12										
15												
20												

型式	Type	M-L	BSET		SBSET		Type	M-L	BSET		SBSET	
			NTS標準單價	NTS折扣單價	NTS標準單價	NTS折扣單價			NTS標準單價	NTS折扣單價	NTS標準單價	NTS折扣單價
BSET SBSET	4-8	8					6-20	25				
		10						30				
		12						35				
	5-10	14					40					
		16					45					
		20					50					
		25					55					
		30					60					
	6-10	35					65					
		40					70					
		45					75					
		50										
		55										
	8-12	14										
		16										
20												
25												
30												
6-10	35											
	40											
	45											
	50											
	55											
6-10	60											
	65											
	70											
	75											

Order 訂購範例 **型式**
BSET5-10
BSET4-8

Delivery 出貨日 **WEB WOS**

Price 價格 **WEB WOS**

Order 訂購範例 **型式**
SCBJ6-10
PSET3-6

Delivery 出貨日 **WEB WOS**

Price 價格 **WEB WOS**