


新商品 NEW

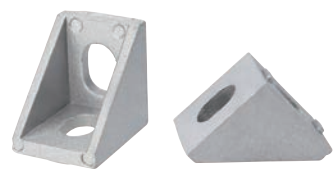

代表型號：LBSB8-4040

19 20個起訂 元/個

最低為標準品 64折


數量	折扣	出貨日
20~499	-	1日

若超過以上訂購數量，交期另外洽詢。實際出貨日與價格以「訂購」時報價單中的內容為準。




雙邊突起型


LBSB6-2020
LBSBL6-2028
LBSB8-4040

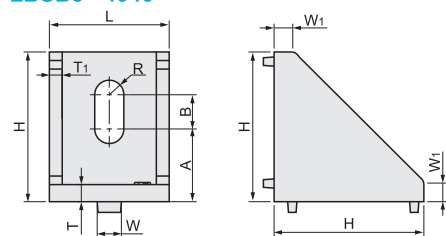


LBSB8-3030

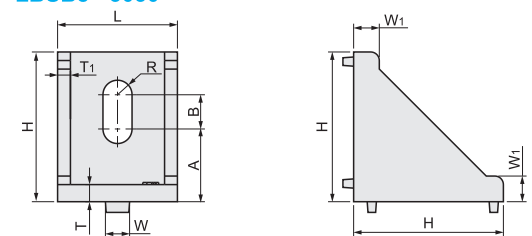

LBSB8-3680

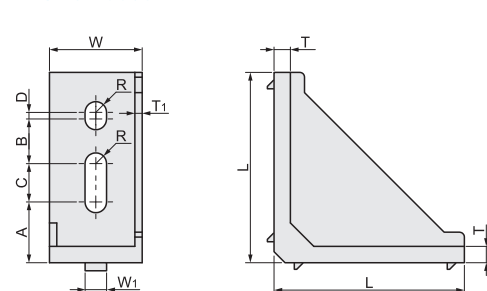


LBSB8-6060
LBSB8-8080

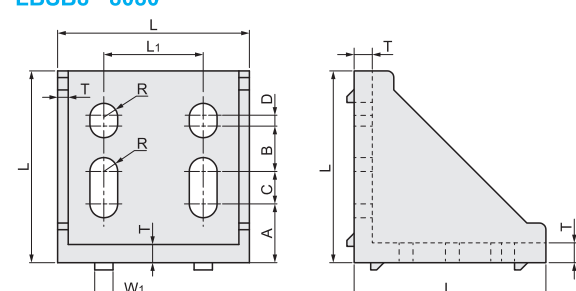


單邊突起型


LBSBK6-2020

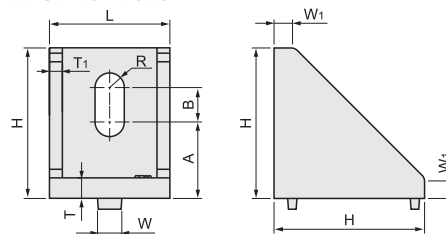


LBSBK8-3030

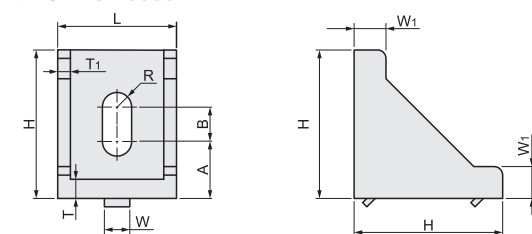


LBSBK8-4040

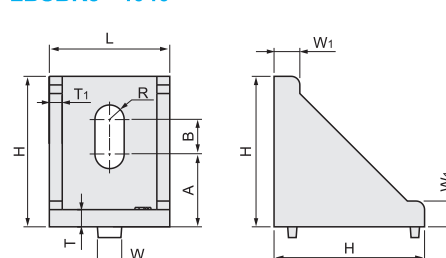


LBSBK8-6060

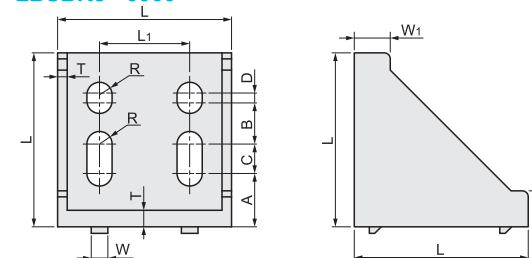

LBSBK8-3680L (左側用)

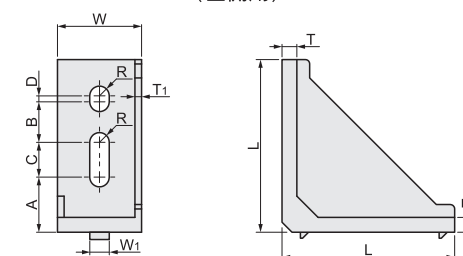

LBSBK8-3680R (右側用)

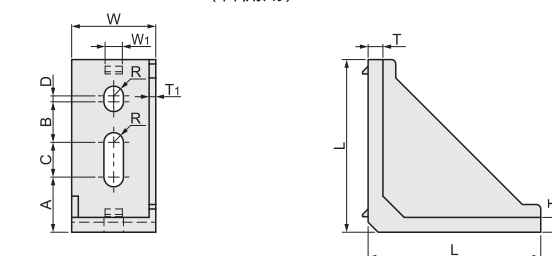

材質 ADC12
表面處理 噴砂

雙邊突起型

型式	適用 鋁擠型規格	L	W	W1	H	A	B	R	T	T1
LBSB6-2020	2020	17	4.5	3	20	9	3	3.3	3	2
LBSBL6-2028	3030	19.6	5.8	5.5	27.6	14.7	3.6	3.4	3.4	2.2
LBSB8-3030	3030	28	6	7	35	13.5	8	3.5	4	3
LBSB8-4040	4040	35	7.8	7.5	40	12	15	4.8	5	4

型式	適用 鋁擠型規格	L	L1	W	W1	A	B	C	D	R	T	T1
LBSB8-3680	4040	78	-	38	7.8	24.9	18.3	15.7	2.7	4.4	6.7	3
LBSB8-6060	6060	58	30	-	5.6	17.8	14.4	9.8	2	4.2	5.5	3.2
LBSB8-8080	8080	79	40	-	7.8	21.7	18.6	16.4	4.3	4.2	6.8	4.5

單邊突起型

型式	適用 鋁擠型規格	L	L1	W	W1	H	A	B	C	D	R	T	T1
LBSBK6-2020	2020	17	-	4.5	3	20	9	3	-	-	3.3	3	2
LBSBK8-3030	3030	28	-	6	7	35	13.5	8	-	-	3.5	4	3
LBSBK8-4040	4040	35	-	7.8	7.5	40	12	15	-	-	4.8	5	4
LBSBK8-6060	6060	58	30	5.6	12	-	17.8	14.4	9.8	2	4.2	5.5	3.2
LBSBK8-3080L LBSBK8-3080R	4080	78	-	38	7.8	-	24.9	18.3	15.7	2.7	4.4	6.7	3

Order 訂購範例

型式 LBSB8-4040

型號生成方法



方法1 MISUMI官網搜尋
Type LBSB8-4040
於網頁搜尋生成訂購型號

方法2 關鍵字

步驟1 MISUMI官網搜尋
步驟2 經濟型品牌選定
關鍵字 鋁擠型角撐架
於網頁搜尋生成訂購型號

步驟2 經濟型品牌選定

關鍵字 鋁擠型角撐架

於網頁搜尋生成訂購型號

