


块状型芯

—直杆型/带肩型—



RoHS 10



—直杆型— SPHD · BCSS□

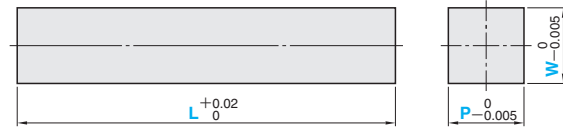

—带肩型— BCS□

 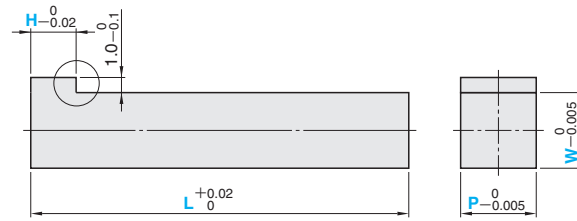

肩部の退刀槽

P · W尺寸公差 $0_{-0.005}^0$

型号		材质	硬度
直杆型	带肩型		
SPHD	BCSH	SKH51	61~64HRC
BCSSX	BCSX	STAVAX ESR®	27~35HRC
BCSSR	BCSR	RIGOR®	53~55HRC
BCSSV	BCSV	ORVAR®	47~49HRC
BCSSA	BCSA	SUPREME	51~53HRC
BCSSN	BCSN	NAK80	37~43HRC

STAVAX ESR®, ORVAR®, SUPREME 及 RIGOR® 为Uddeholm株式会社の注册商标。

■直杆型

型号 Type	指定单位0.01mm		
	L	P	W
SPHD (SKH51)	10.00 } 70.00* (100.00)	1.00~ 1.99	1.00~10.00
BCSSX (STAVAX ESR®)		2.00~10.00	1.00~20.00
BCSSR (RIGOR®)		10.01~20.00	2.00~20.00

*P<2.00...L≤50.00 W<2.00...L≤50.00
BCSSR型W≤3.49...L≤50.00
SPHD(L70.01~100.00), BCSSX...P·W≥5.01

ⓁL尺寸的“()”内数值仅适用于SPHD规格。

■带肩型

型号 Type	指定单位0.01mm			H
	L	P	W	
BCSH (SKH51)	10.00 } 70.00* (100.00)	1.00~ 1.99	1.00~10.00	4
BCSX (STAVAX ESR®)		2.00~10.00	1.00~20.00	
BCSR (RIGOR®)		10.01~20.00	2.00~20.00	6

*P<2.00...L≤50.00 W<2.00...L≤50.00
BCSR型W≤3.49...L≤50.00
BCSH(L70.01~100.00), BCSX...P·W≥5.01

ⓁL尺寸的“()”内数值仅适用于BCSH规格。



Order 订货范例
型号 — L — P — W — H(仅BCS□)
BCSR — 20.00 — P3.20 — W3.00 — H6



Delivery 交货期
•SPHD · BCSH
5 天发货
•BCSSR · BCSR · BCSSV · BCSV · BCSSX
•BCSSA · BCSA · BCSSN · BCSN · BCSX
7 天发货
Ⓛ上海·广州发货
Ⓛ数量>51时, 请另询交货期。



Alterations 追加加工
型号 — L — P — W — H(HC) — (TC)
BCSR — 20.00 — P3.20 — W3.00 — HC5 — TC0.5

Alteration	Code	Spec.	Alteration	Code	Spec.
	TC	变更肩部宽度(0.3<TC≤3.0) 仅限BCSX(0.3<TC<1.0) TC尺寸指定单位0.1mm ⓁL10.00~30.00...0.3<TC≤1.5 Ⓛ30.01~50.00...0.3<TC≤2.5 Ⓛ50.01~70.00...0.3<TC≤3.0		HC	变更肩部厚度 HC尺寸指定单位0.1mm Ⓛ2<HC<H

■精度基准

精度基准	材质
翘曲 	a ≤ 0.01 P · W < 2... a ≤ 0.05 2 ≤ P · W... a ≤ 0.01

精度基准	材质
垂直度 	b ≤ 0.01
平行度 	P · W ≤ 10... C ≤ 0.005 10 < P · W... C ≤ 0.01

入れ子
ブロックコアピン

固定块
块状型芯