


# 锁模板

—标准型—

# 锁模板

—全長指定型—

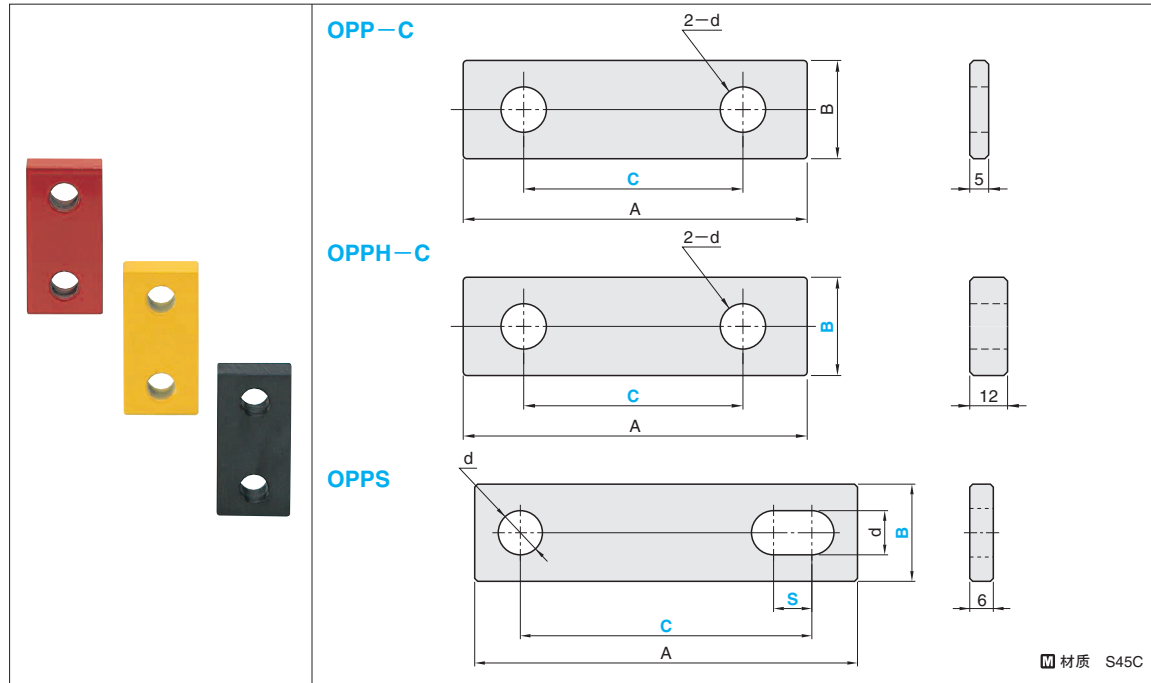

B	A	d	型号		Color 安全色
			Type	C	
16	30	7	OPP-C	15	R (红色) Y (黄色) N (黑色)
	40				
	50				
	60				
	70				
	80				
	90				
20	100	9	OPP-C	80	R (红色) Y (黄色) N (黑色)
	110				
	120				

d	A	型号		C	S 选择	Color 安全色
		Type	B			
7	50	OPP-C	25	30	5 8 10	R (红色) Y (黄色) N (黑色)
	60					
	70					
	80					
	100					
9	110	OPP-C	38	90	5 8 10	R (红色) Y (黄色) N (黑色)
	120					
	130					
	140					
	150					

d	A	型号		C	Color 安全色
		Type	B		
9	40	OPPH-C	25	20	R (红色) Y (黄色) N (黑色)
	50				
	60				
	70				
	80				
14	90	OPPH-C	38	50	R (红色) Y (黄色) N (黑色)
	100				
	110				
	120				
	130				

Order 订货范例

型号	C	S	Color
OPP-C 100			Y
OPPH-C 25	50		R
OPPS 25	30	5	Y

•OPP-C・OPPH-C


**5** 天发货

上海・广州发货  
数量 > 101时, 请另询交货期。

•OPPS

**6** 天发货

上海・广州发货  
数量 > 101时, 请另询交货期。

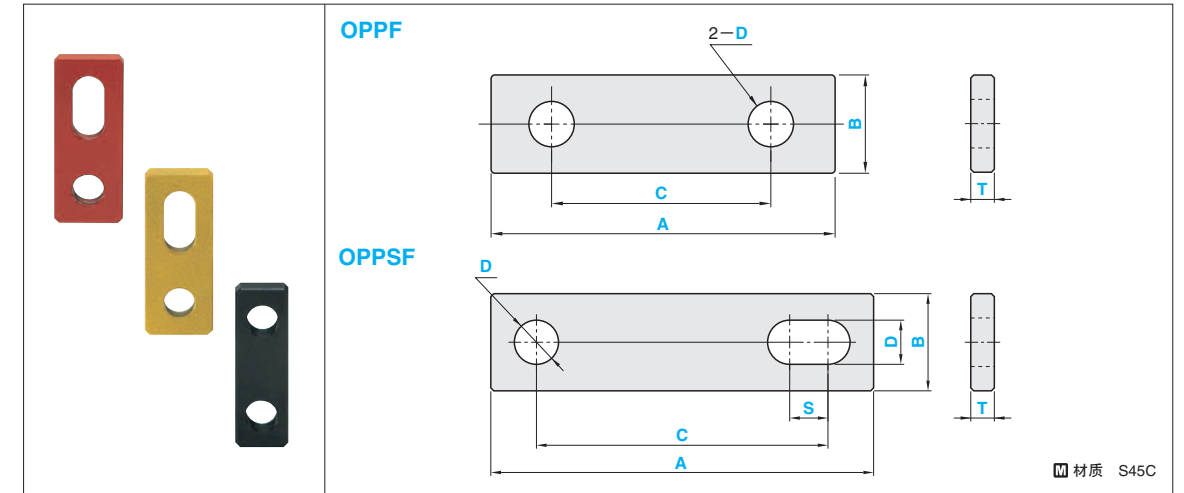

型号 Type	指定单位1mm			选择		Color 安全色
	B	A	C	D	T	
OPPF	16	30~200 (D 7时, A ≥ 30 D 9时, A ≥ 40 D 14时, A ≥ 50)	2D < C <= A - 2D	7 9	5 12	R (红色) Y (黄色) N (黑色)
	20					
	25					
	38					
				7 9	5 12	
				9 14	12 16	
				9 14	12 16	

型号 Type	指定单位1mm			选择		Color 安全色	
	B	A	C	S	D T		
OPPSF	16	30~200 (D 7时, A ≥ 30 D 9时, A ≥ 40 D 14时, A ≥ 50)	2D < C <= A - 2D	S < C - 2D	7 9	6 12	R (红色) Y (黄色) N (黑色)
	20						
	25						
	38						
					7 9	6 12	
					9 14	12 16	
					9 14	12 16	

Order 订货范例

型号	A	C	S	D	T	Color
OPPF 16	A50	C30		D9	T5	R
OPPSF 16	A60	C30	S10	D9	T6	Y

Delivery 交货期

**9** 天发货

上海・广州发货  
数量 > 101时, 请另询交货期。