


ノックピン 定位销

盒装销售指南
同一规格批量购买绝对合算!
(仅限右表尺寸产品)
订货方法 交货期
P.1113


型号	适合尺寸		每盒数量
	D	L	
MSTH	5 10 15	20 25 30	100支
	6 10 15 20 25 30	30 40	200支
	8 20 30 40	30 40	
	10	30 40	

ネジ・ワッシャ
小物

螺栓・垫圈
小零件

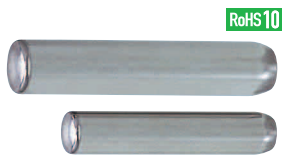


MS (直杆型)

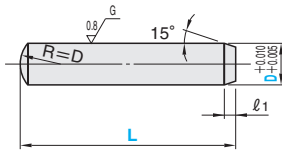


材质 SUJ2
硬度 58HRC~

MSV (高精型)

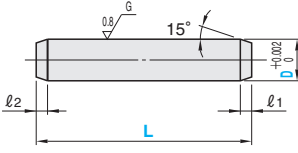


材质 SUJ2
硬度 58HRC~

MSTP (带拉拔螺纹精密型)

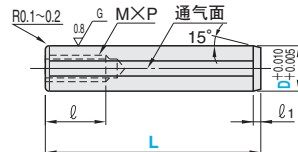


D5·6且L尺寸为10时,螺纹底孔有时会贯通。
材质 SUJ2
硬度 58HRC~

MST (带拉拔螺纹p6型)

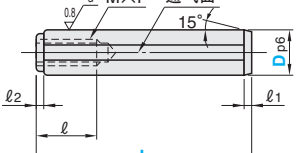

D5·6且L尺寸为10时,螺纹底孔有时会贯通。

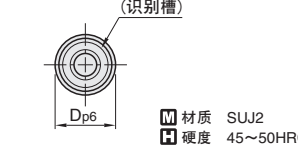

材质 SUJ2
硬度 45~50HRC

l1, l2尺寸为参考值。由于是外圆磨加工, 有时会比下表所记尺寸要大。

l1	型号		L												
	Type	D													
0.4	MS	1	6	8	10										
0.6		1.5	6	8	10										
1.0		2	6	8	10	15	20								
		2.5	6	8	10	15	20	25	30						
		3	6	8	10	15	20	25	30	35	40				
1.5		4	8	10	15	20	25	30	35	40	45	50			
		5	8	10	15	20	25	30	35	40	45	50			
2.0		6	8	10	15	20	25	30	35	40	45	50	55	60	
		8	10	15	20	25	30	35	40	45	50	55	60	65	70
2.5		10	15	20	25	30	35	40	45	50	55	60	65	70	80
		12	20	25	30	35	40	45	50	55	60	70	80		
3.0		13	30	40	50	60	70	80							
		13	30	40	50	60	70	80							

l1	l2	型号		L											
		Type	D												
1.0	0.2	MSV	2	6	8	10									
			3	8	10	15	20	25	30						
1.5	4		10	15	20	25	30								
	5		10	15	20	25	30								
	6		10	15	20	25	30								
2.0	8		10	15	20	25	30								
	6		20	30	40										
2.5	8		20	30	40	50	60	70	80						
	10		30	40	50	60									
3.0	10		30	40	50	60									
	10		30	40	50	60									

高精度型定位销是在恒温室内测量的。


l1	M	P	l	D	型号		L											
					Type	D												
1.5	3	0.5	*6	+0.010 +0.005	MSTP	5	10	15	20	25	30							
						6	10	15	20	25	30	35	40	50				
2.0	8	15	20			25	30	35	40	45	50	60	70	80				
	10	15	20			25	30	35	40	45	50	60	70	80				
	12	20	30			40	50	60	70	80								
2.5	8	15	20			25	30	35	40	45	50	60	70	80				
	15	40	50			60	70	80										
3.0	1.25	16	40			50	60	70										

*D=5时, l=6为参考值 *仅D=6, L=10时, l=6


l1	l2	M	P	l	Dp6	型号		L													
						Type	D														
1.5	0.5	3	0.5	*6	+0.020 +0.012	MST	5	10	15	20	25	30									
							6	10	15	20	25	30	35	40	50						
2.0							8	15	20	25	30	35	40	45	50	60	70	80			
							10	15	20	25	30	35	40	45	50	60	70	80			
							12	20	30	40	50	60	70	80							
2.5							13	40	50	60	70	80									
							16	40	50	60	70	80									
3.0							10	15	20	25	30	35	40	45	50	60	70	80			
							18	50	60	70	80										

*D=5时, l=6为参考值 *仅D=6, L=10时, l=6

MSTM (带拉拔螺纹m6型)

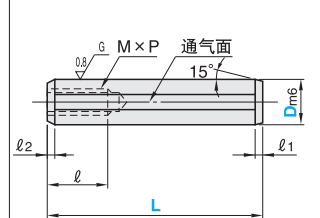


D5·6及L尺寸为10时, 螺纹底孔有时会贯通。

 


材质 SUJ2
硬度 45~50HRC

MTT (带拉拔螺纹锥型)

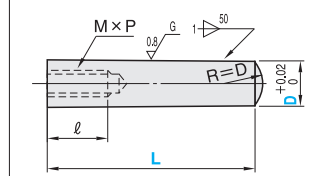


材质 SK4
硬度 45~50HRC

MSSH (直杆型)

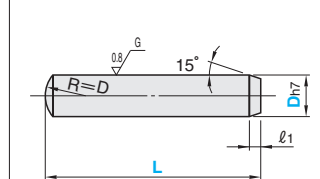

材质 SUJ2
硬度 58HRC~

MSTH (带拉拔螺纹h7型)

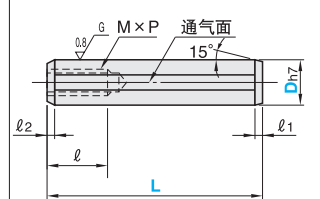

D5·6且L尺寸为10时,螺纹底孔有时会贯通。D10且L尺寸为15时,螺纹底孔有时会贯通。

材质 SUJ2
硬度 45~50HRC

l1, l2尺寸为参考值。由于是外圆磨加工, 有时会比下表所记尺寸要大。

l1	l2	M	P	l	Dm6	型号		L											
						Type	D												
1.5	0.3	3	0.5	*6	+0.012 +0.004	MSTM	5	10	15	20	25	30							
							6	10	15	20	25	30	35	40	50				
2.0							8	15	20	25	30	35	40	45	50	60	70	80	
							10	15	20	25	30	35	40	45	50	60	70	80	
							12	20	30	40	50	60	70	80					
2.5							13	40	50	60	70	80							
							15	40	50	60	70	80							
3.0							1.5	10	15	20	25	30	35	40	45	50	60	70	80
							1.5	18	50	60	70	80							

*D=5时, l=6为参考值 *仅D=6, L=10时, l=6

MXP	l	型号		L											
		Type	D												
M5X0.8	9	MTT	8	30	40										
			10	40	50										
M6X1.0	10	MTT	12	40	50										
			13	50	60										
M8X1.25	14	MTT	16	60	70										
			16	60	70										

l1	Dh7	型号		L											
		Type	D												
1.0	0 -0.010	MSSH	2	6	8	10	15								
			3	8	10	15	20								
			4	10	15	20									
1.5	0 -0.012	MSSH	4	10	15	20									

l1	l2	M	P	l	Dh7	型号		L												
						Type	D													
1.5	0.3	3	0.5	*6	0 -0.012	MSTH	5	10	15	20	25	30								
							6	10	15	20	25	30	35	40	50					
2.0							8	15	20	25	30	35	40	45	50	60	70	80		
							10	15	20	25	30	35	40	45	50	60	70	80	100	120
							12	20	30	40	50	60	70	80	100	120				
2.5							13	40	50	60	70	80	100	120						
							16	40	50	60	70	80	100	120	150					

*D=5时, l=6为参考值。*仅D=6, L=10时, l=6 MSTH的盒装产品 P.1113

Order 订货范例 型号 MS 2 L 20

Delivery 交货期 库存品

通气面深度 0.15
*由于是滚筒抛光, 仅供参考。
所有D尺寸采用同一深度
涉及品种: MSTP, MST, MSTM, MSTH

*隔日上海·广州发货 P.41
(17:00前订购的库存品可当日发货。)
*数量>4001时, 请另询交货期。
*MSTM数量>2000时, 请另询交货期。
*MSSH·MSTH数量>601时, 请另询交货期。