




ガスプリング用プレート 一座面固定タイプ
氮气弹簧用板
 一支承面固定型


ガスプリング

氮气弹簧


RoHS10 **FB**



FB45-50-63

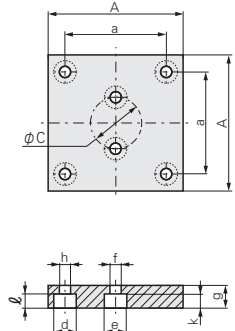


FB75~195

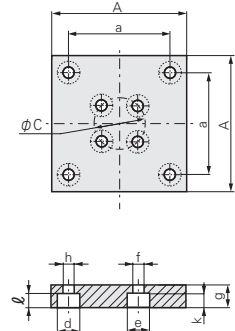


M材 质 相当于S45C
S表面处理 四氧化三铁保护膜(Fe₃O₄)


RoHS10 **FBA**



FBA45-50

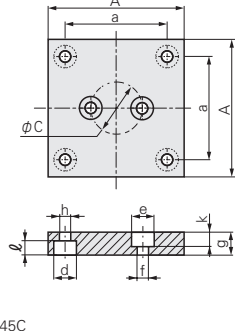


FBA75~195

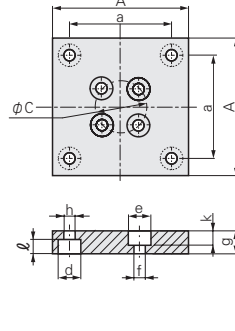


M材 质 相当于S45C
S表面处理 四氧化三铁保护膜(Fe₃O₄)


RoHS10 **FBB**



FBB45~63

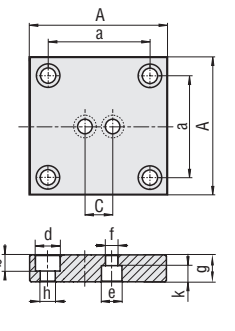

FBB75~195

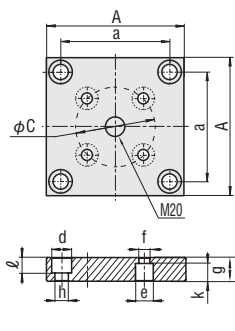

M材 质 相当于S45C
S表面处理 四氧化三铁保护膜(Fe₃O₄)

A	a	C	g	e	d	f	h	k	ℓ	Catalog No.	适用氮气弹簧						模具固定用 建议螺栓 4个	氮气弹簧固定用 建议螺栓 2个 or 4个	
											GSV	GST	GSH	GSK	GSSC	GSU			
70	50	20	20	15	15	9	9	14	12	FB	45	750	750	—	500	—	—	CB 8-20	CB 8-18
75	56.5	20	20	15	15	9	9	14	12		50	1000	1500	1000	750	—	—	CB 8-20	CB 8-18
100	73.5	20	20	15	18	9	11	12	12		63	1500	—	—	—	—	—	CB10-25	CB 8-18
100	73.5	40	20	15	18	9	11	14	12		75	2400	—	2400	1500	4700	—	CB10-25	CB 8-18
120	92	60	20	15	20	9	13.5	14	13		95	4200	—	4200	3000	—	—	CB12-25	CB 8-18
140	109.5	80	20	18	20	11	13.5	15	13		120	6600	6600	6600	5000	—	—	CB12-25	CB10-20
190	138	100	25	18	26	11	17.5	15	17		150	9500	12000	9500	—	7500	—	CB16-35	CB10-25
210	170	120	25	20	26	13.5	17.5	13	17		195	20000	—	—	10000	—	—	CB16-35	CB12-25

☞FB符合ISO 11901-2标准。(※FB63除外)

A	a	C	g	e	d	f	h	k	ℓ	Catalog No.	适用氮气弹簧						模具固定用 建议螺栓 4个	氮气弹簧固定用 建议螺栓 2个 or 4个	
											GSV	GST	GSH	GSK	GSSC	GSU			
70	50	20	20	15	18	9	11	14	12	FBA	45	750	750	—	500	—	—	CB10-25	CB 8-18
75	56.5	20	20	15	18	9	11	14	12		50	1000	1500	1000	750	—	—	CB10-25	CB 8-18
100	73.5	40	20	15	18	9	11	14	12		75	2400	—	2400	1500	4700	—	CB10-25	CB 8-18
120	92	60	20	15	20	9	13.5	14	13		95	4200	—	4200	3000	—	—	CB12-25	CB 8-18
140	109.5	80	20	18	20	11	13.5	15	13		120	6600	6600	6600	5000	—	—	CB12-25	CB10-20
190	138	100	25	18	26	11	17.5	15	17		150	9500	12000	9500	—	7500	—	CB16-35	CB10-25
210	170	120	25	20	26	13.5	17.5	15	17		195	20000	—	—	10000	—	—	CB16-35	CB12-25

☞FBA符合Renault EM24.54.700标准。

A	a	C	g	e	d	f	h	k	ℓ	Catalog No.	适用氮气弹簧						模具固定用 建议螺栓 4个	氮气弹簧固定用 建议螺栓 2个 or 4个	
											GSV	GST	GSH	GSK	GSSC	GSU			
70	50	20	20	15	15	9	9	12	12	FBB	45	750	750	—	500	—	—	CB 8-20	CB 8-20
75	56.5	20	20	15	15	9	9	12	12		50	1000	—	1000	750	—	—	CB 8-20	CB 8-20
100	73.5	20	20	15	18	9	11	12	12		63	1500	1500	1500	—	—	—	CB10-25	CB 8-20
100	73.5	40	20	15	18	9	11	12	14		75	2400	—	2400	1500	4700	—	CB10-25	CB 8-20
120	92	60	20	15	20	9	13.5	14	13		95	4200	—	4200	3000	—	—	CB12-25	CB 8-20
140	109.5	80	20	18	20	11	13.5	15	13		120	6600	6600	6600	5000	—	—	CB12-25	CB10-20
190	138	100	20	18	20	11	13.5	15	13		150	9500	12000	9500	—	7500	—	CB16-35	CB10-25
210	170	120	25	20	26	13.5	17.5	15	17		195	20000	—	—	10000	—	—	CB16-35	CB12-25

☞FBB符合Mezcedes Benz B8 0132 110 008 801标准和BMW B2 4009标准。



Order
订货范例

Catalog No.

FB50
FBA45
FBB75




Delivery
交货期

请通过 **MISUMI** 询价。
(<https://www.misumi.com.cn>)



Example
使用范例

安装FB时

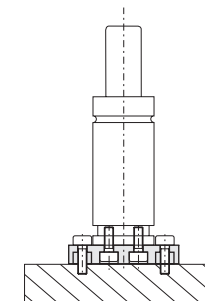

安装FBA・FBB时

